



GN 420 → Page 448

GN 421 → Page 449  
GN 421.10 → Page 450  
GN 421.11 → Page 451  
GN 421.12 → Page 451DIN 464 → Page 457  
M6 ... M10DIN 466 → Page 456  
M6 ... M12

GN 534 → Page 442



GN 534 → Page 443

GN 633  
GN 633.1GN 634  
GN 634.1GN 5334\* → Page 414  
GN 5334.4 → Page 414GN 5334\* → Page 415  
GN 5334.4 → Page 415GN 5337.2 → Page 406  
Size 32 ... 63GN 5337.2 → Page 407  
Size 32 ... 63

GN 5337.4



GN 5337.4

DIN 6335 → Page 420 / 422  
KT / AL  
Size 32 ... 63GN 6335.4 → Page 423  
GN 6335.5 → Page 423  
STDIN 6336\* → Page 396 / 398  
KT / AL  
Size 25 ... 63GN 6336.4\* → Page 401  
GN 6336.5 → Page 401  
ST  
Size 25 ... 63GN 6336.10 → Page 402  
GN 6336.11 → Page 403  
GN 6336.12 → Page 404


GN 6336.3 → Page 404

\* see also GN 6336.13 (with mounted loss protection) → Page 405



## Specification

Recess for retaining rings and retaining rings GN 111.6 (Stainless Steel) according standard sheet  
→ Page 879

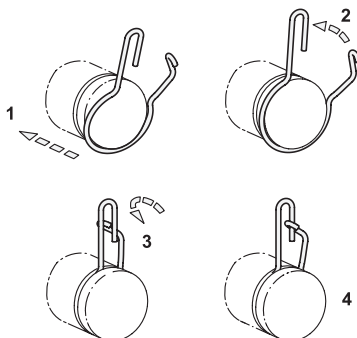

## Information

The standards listed can be delivered with loss protection GN 111.7 with a recess and a retaining ring.

The retaining rings are delivered unassembled, as disassembly can lead to their deformation.

Ball chains GN 111 / GN 111.5 resp. retaining cables GN 111.2 / GN 111.4 are to be ordered separately.

see also...

- Star knobs GN 6336.13 (with mounted loss protection) → Page 405
- Ball chains GN 111 → Page 876
- Stainless Steel-Ball chains GN 111.5 → Page 876
- Stainless Steel-Retaining cables GN 111.2 → Page 877
- Spiral retaining cables GN 111.4 → Page 878

How to order

**GN 111.7**

Knurled thumb screw GN 421-M5-20  
with loss protection **GN 111.7**

