



GN 420 → Page 448



GN 421 → Page 449
GN 421.10 → Page 450
GN 421.11 → Page 451
GN 421.12 → Page 451



DIN 464 → Page 457
M6 ... M10



DIN 466 → Page 456
M6 ... M12



GN 534 → Page 442



GN 534 → Page 443



GN 633
GN 633.1



GN 634
GN 634.1



GN 5334* → Page 414
GN 5334.4 → Page 414



GN 5334* → Page 415
GN 5334.4 → Page 415



GN 5337.2 → Page 406
Size 32 ... 63



GN 5337.2 → Page 407
Size 32 ... 63



GN 5337.4



GN 5337.4



DIN 6335 → Page 420 / 422
KT / AL
Size 32 ... 63



GN 6335.4 → Page 423
GN 6335.5 → Page 423
ST



DIN 6336* → Page 396 / 398
KT / AL
Size 25 ... 63



GN 6336.4* → Page 401
GN 6336.5 → Page 401
ST
Size 25 ... 63



GN 6336.10 → Page 402
GN 6336.11 → Page 403
GN 6336.12 → Page 404




GN 6336.3 → Page 404

* see also GN 6336.13 (with mounted loss protection) → Page 405



Specification

Recess for retaining rings and retaining rings GN 111.6 (Stainless Steel) according standard sheet
→ Page 879

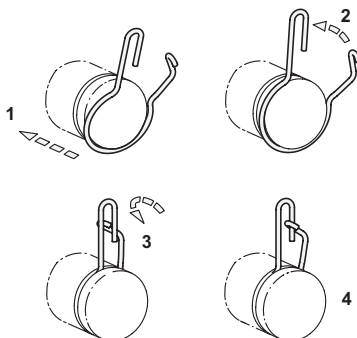

Information

The standards listed can be delivered with loss protection GN 111.7 with a recess and a retaining ring.

The retaining rings are delivered unassembled.

Ball chains GN 111 / GN 111.5 resp. retaining cables GN 111.2 / GN 111.4 are to be ordered separately.

see also...

- Star knobs GN 6336.13 (with mounted loss protection) → Page 405
- Ball chains GN 111 → Page 876
- Stainless Steel-Ball chains GN 111.5 → Page 876
- Stainless Steel-Retaining cables GN 111.2 → Page 877
- Spiral retaining cables GN 111.4 → Page 878

How to order

GN 111.7

Knurled thumb screw GN 421-M5-20
with loss protection **GN 111.7**

