


Type SG




1 Type

Operation


- RG** with knurled knob in plastic GN 7336
- KG** with wing knob in plastic
- HG** with lever in plastic
- SG** with St. Steel-Star knob
- KGN** with St. Steel-Wing knob
- HGN** with St. Steel-Lever

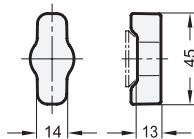

Type KGN

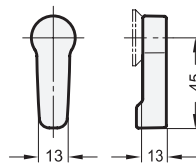


Type HGN

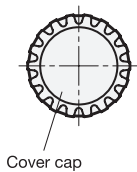


Cover cap

Type RG

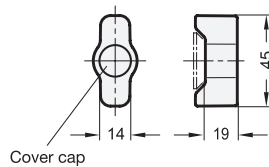

Cover cap

Type KG

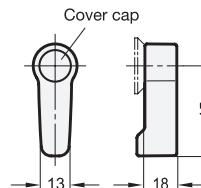

Cover cap
Type HG

2

Latch distance **A**

6	10	14	18	20	22	24	26	28	30	34	38	40	50
---	----	----	----	----	----	----	----	----	----	----	----	----	----

Specification

- Lock housing
Stainless Steel
AISI 303
- Latch
Stainless Steel AISI 304
- Star knobs (Type SG)
Stainless Steel AISI 304
- Sheet metal, drawn
- Hub, welded
- Operating handles (Type KGN, HGN)
Stainless Steel AISI CF-8
- Operating handles (Type RG, KG, HG)
Plastic (Polyamide PA)
black, matte
- Protection class IP 65
- *Stainless Steel characteristics* → Page 1489
- RoHS

3

Information

Latches GN 115 lock by a turning operation limited to 90° which moves the locking behind the door frame. The bevels of the latch ease the closing of the door.

Latches with different cranks cover a latch distance A from 6 to 50 mm.

The operating bolt is fitted with an O-ring for sealing.

Stainless Steel-Latches GN 115 are supplied with loosely enclosed locking.

see also...

- *Construction and assembly instructions* → Page 897
- *List of latch types* → Page 892 ff.
- *Stainless Steel-Latches GN 115 (lockable)* → Page 902
- *IP-Protection classes* → Page 1482

How to order

GN 115-SG-18-NI

1	Type
2	Latch distance A
3	Material