


Application example

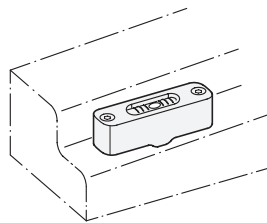

4 Sensitivity

- 6 Angle minutes, bubble move by 2 mm
- 50 Angle minutes, bubble move by 2 mm

5 Type

- AV aligned, mounting from the front side (not adjustable)
- JV adjustable, mounting from the front side

2

Length l	b	d ₁	d ₂	h ₁	h ₂	h ₃	m
54	15,5	3,4	6,3	14,5	11,3	1	45

Specification

- Housing
 - Aluminum anodized, natural color ALN
 - anodized, black ALS
- Spirit level element
 - Glass body
 - Filling green-transparent G
- Casting compound mineral-based
- RoHS

On request

- Filling, colorless-transparent
- other sensitivities

Information

Screw-on spirit levels GN 2283 are used to check the horizontal position of jigs, machines, devices, appliances and instruments.

The spirit levels of type AV are aligned in relation to the reference surface so that the bubble is centered in the middle of the marking lines once the horizontal position of the contact surface is reached.

The spirit levels of type JV are aligned during installation using the fastening holes. An alignment guide on the bottom serves as a pivot point. With careful tightening, it is possible to achieve an alignment that places the bubble between the middle marking lines.

see also...

- General information on bull's eye spirit levels and screw-on spirit levels → Page 243

How to order

1	Material / Finish
2	Length l
3	Filling
4	Sensitivity
5	Type

GN 2283-ALS-54-G-50-AV

