 
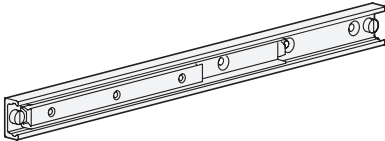
 
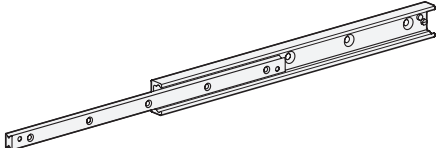
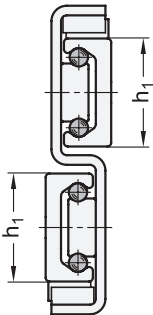
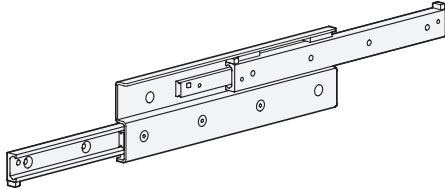
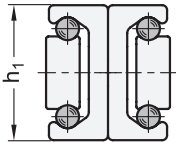
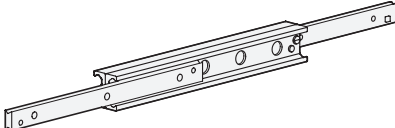
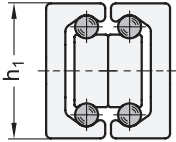
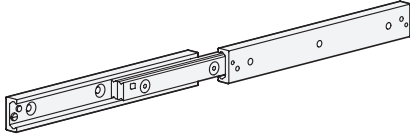



# Linear slides

Types

<p><b>Linear slides</b> with inside traversal distance <b>GN 2402</b> → Page 1291</p>			<p>3.1 3.2</p>
<p><b>Telescopic linear slides</b> with partly outside traversal distance (Partial extension) <b>GN 2404</b> → Page 1292</p>			<p>3.3 3.4</p>
<p><b>Telescopic linear slides</b> with S-shaped intermediate profile (Full extension) <b>GN 2406</b> → Page 1293</p>			<p>3.5 3.6 3.7</p>
<p><b>Telescopic linear slides</b> with rails connected in H-shape (Full extension) <b>GN 2408</b> → Page 1294</p>			<p>3.8</p>
<p><b>Telescopic linear slides</b> with runners connected in dual configuration (Full extension) <b>GN 2410</b> → Page 1295</p>			<p>3.9 </p>