


Application example

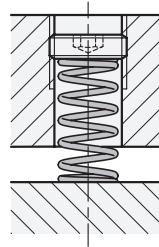

- 2** Type
- A** Without thread coating
  - PRB** With thread coating (polyamide allround coating)



d		h	A/F
<b>GN 252</b>	<b>GN 252.5</b>		
M 12 x 1,5	M 12 x 1,5	10	6
M 16 x 1,5	M 16 x 1,5	10	8
M 20 x 1,5	M 20 x 1,5	12	10
M 24 x 1,5	M 24 x 1,5	12	14
M 27 x 1,5	M 27 x 1,5	12	14
M 30 x 1,5	-	12	17
M 33 x 1,5	-	12	17

**Specification**

- **GN 252**  
Steel
  - Property class 5.8
  - Blackened
- **GN 252.5**  
Stainless steel AISI 303
- *Strength Values of Screws* → Page 2152
- *Stainless Steel Characteristics* → Page 2166
- **RoHS**

**Information**

The thread locking PRB (polyamide allround coating) is a clamping lock which prevents the locking screw from being inadvertently being loosened and becoming detached.

see also...

- *Threaded Plugs GN 749 (with Sealing Ring Rubber)* → Page 1592
- *Threaded Plugs DIN 906 (with Conical Thread)* → Page 1593
- *Threaded Plugs DIN 908* → Page 1594
- *More Information to Thread Lockings* → Page 2173 ff.

How to order (Steel)	1 d
<b>GN 252-M24x1,5-A</b>	2 Type

How to order (Stainless steel)	1 d
<b>GN 252.5-M16x1,5-PRB</b>	2 Type

