


x = ground

**Application example**

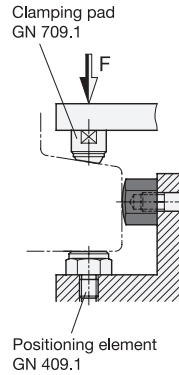

**3 Type**

- B** Smooth contact face
- K** Spherical contact face
- R** Serrated contact face

<b>1</b> h Type B: ±0,01 Type K / R: ±0,01	<b>2</b> d <sub>1</sub>	d <sub>2</sub> Type B / R	t min.	A/F	e Width across corners
15	M 8	17	6	17	19,4
20	M 10	19	10	19	21,9
20	M 12	22	10	22	25,2
25	M 8	17	12	17	19,4
25	M 12	22	15	22	25,2
30	M 10	19	15	19	21,9
30	M 12	22	18	22	25,2
30	M 16	30	20	30	33
40	M 10	19	15	19	21,9
40	M 12	22	18	22	25,2
50	M 12	22	18	22	25,2
50	M 16	30	24	30	33

**Specification**

- Steel
  - hardened
  - blackened
- RoHS

**Information**

Positioning elements GN 409.2 with female thread are designed for use as locating plungers, stops and thrust blocks.

**How to order**

**GN 409.2-25-M8-R**

<b>1</b>	<b>h</b>
<b>2</b>	<b>d<sub>1</sub></b>
<b>3</b>	<b>Type</b>

3.1  
3.2  
3.3  
3.4  
3.5  
3.6  
3.7  
3.8  
3.9

