


ROSTFREI  
Inox  
Stainless  
Steel

**4 Type**  
**OS** without scale  
**LS** with scale (mm-graduation)

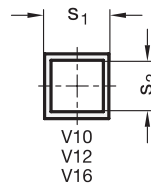

d <sub>1</sub> Diameter D Material NI	s <sub>1</sub> Square V Material AL	Length l								d <sub>2</sub>	s <sub>2</sub>	k
		100	150	200	250	300	350	400				
D 8	-	100	150	200	250	300	350	400	-	-	15	
D 10	V 10	100	150	200	250	300	350	400	-	7	15	
D 12	V 12	100	150	200	250	300	350	400	9	9	15	
D 15	-	100	150	200	250	300	350	400	12	-	20	
D 16	V 16	100	150	200	250	300	350	400	13	13	20	
D 20	-	100	150	200	250	300	350	400	16	-	25	

**Specification**

- Retaining rods / tubes, round  
Stainless Steel AISI 304  
ground **NI**
- Retaining square tubes  
Aluminum  
anodized natural color **AL**
- Longitudinal scale engraved  
in laser precision
- Stainless Steel characteristics → Page 1489
- RoHS-compliant

**On request**

- Special scales

**3 Information**

The outside dimensions of the retaining rods / retaining tubes GN 480.1 are matched for use with clamp mountings.

The retaining tubes can also be used as cable lead-through.

siehe auch...

- Tube end plugs GN 991 → Page 1278

How to order (Retaining rod)

**GN 480.1-D10-150-NI-LS**

1	d <sub>1</sub>
2	Length l
3	Material
4	Type

How to order (Retaining tube)

**GN 480.1-V16-300-AL-OS**

1	s <sub>1</sub>
2	Length l
3	Material
4	Type