


Mounting example

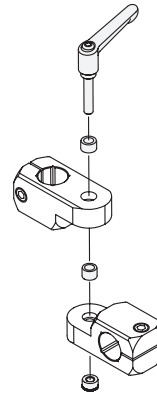

- 3** Type
- S** with cylinder head screw DIN 912
 - K** with adjustable hand levers

1 **2**

d ₁	l ₂	d ₂	d ₃	d ₄	l ₁	l ₃	l ₄	l ₅	l ₆	h ₁	h ₂	Swivel clamp mounting k-dimension
M 4	16	7,5	6,9	7,5	30	11,5	4,5	4	4	24,5	30,5	16
M 5	20	9	8,4	9	30	14	6	5	5	24,5	30,5	20
M 6	25	10,5	9,9	10,5	45	18,5	6,5	7	6	24,5	35	25
M 6	30	10,5	9,9	10,5	45	23,5	6,5	7	6	24,5	35	30

Specification

- Handle
Zinc die casting
plastic coated
silver, RAL 9006, textured finish
- Threaded insert, distance sleeve,
centering bushing, threaded bushing
Stainless Steel AISI 303
- Cylinder head screw DIN 912
Stainless Steel AISI 304
- *Stainless Steel characteristics* → Page 1489
- RoHS

Information

With clamping kits GN 511.1 swivel clamp mountings GN 482 can be combined with T-Swivel clamp mountings GN 483 and attachment clamp mountings GN 484 with the same k-dimensions into swivel clamp mounting joints.

The centering bushing positions the swivel clamp mountings in relation to each other. During assembly, the knurled threaded bushing is inserted by the clamping screw itself and by pressing into one of the two swivel clamp mountings and so serves to clamp the articulated joint.

The matching clamping kits are shown in the dimensional tables of the appropriate swivel clamp mountings.

see also...

- *Swivel clamp mountings GN 482* → Page 1257

How to order

GN 511.1-M5-20-S

- 1** d₁
- 2** l₂
- 3** Type

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9

