




**elesa**  
Original design IF / IFF

**4 Type**

- A** With hand guard, one side
- B** With hand guard, both sides

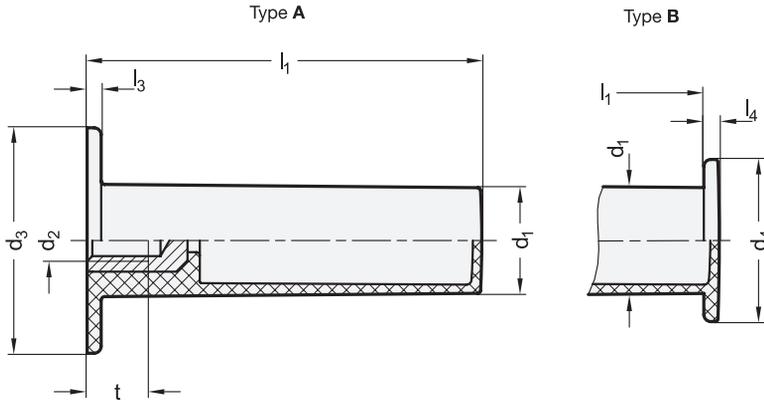

**1**

**2**

<b>d<sub>1</sub></b>	<b>d<sub>2</sub></b>	<b>d<sub>3</sub></b>	<b>d<sub>4</sub></b>	<b>l<sub>1</sub></b>	<b>l<sub>3</sub></b>	<b>l<sub>4</sub></b>	<b>t</b>
30	M 8	64	46	112	4	4	20
30	M 10	64	46	112	4	4	18

**Specification**

- Plastic  
Technopolymer (Polyamide PA)  
- Glass fiber reinforced  
- Temperature resistant up to 130 °C  
- Black, matte finish
- Threaded bushing  
Brass
- *Plastic Characteristics* → Page 2158
- **RoHS**

**Information**

Cylindrical handles GN 539.2 are used as handles for electronic tools such as angle grinders, percussion drills etc. Their special feature is the hand guard on one or both sides.

see also...

- *Fixed Cylindrical Handles GN 539* → Page 48
- *Cylindrical Handles GN 519* → Page 68

How to order

**GN 539.2-30-M8-A**

<b>1</b>	<b>d<sub>1</sub></b>
<b>2</b>	<b>d<sub>2</sub></b>
<b>3</b>	<b>Type</b>