




ELESA Original design EBS+x

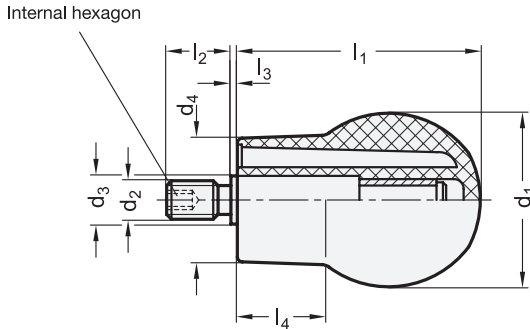

1

2

d ₁	d ₂	d ₃	d ₄ +0,5	l ₁	l ₂	l ₃ ≈	l ₄ ≈
45	M 10	12	32	64	17	1	22

Specification

- Plastic
Technopolymer (Polypropylene PP)
- temperature resistant up to 80 °C
- black, matte
- Spindle
Steel
zinc plated, blue passivated
- *Plastic characteristics* → Page 1483
- **RoHS-compliant**

Information

The revolving ball knob GN 596 is in general used where a pulling action is involved such as on vertically positioned handwheels or cranked handles.

see also...

- *Product family Ergostyle®* → Page 17

How to order

GN 596-45-M10

1 d₁

2 d₂