


elesa

ELESA original design ADT

Assembly examples

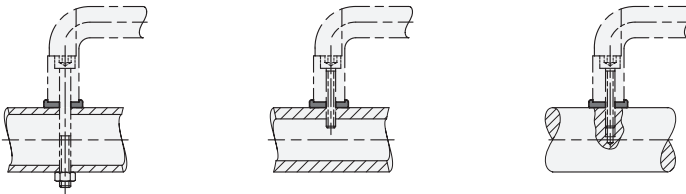

1

2

3

d ₁	Nominal dimension		a	b	d ₂	h ₁	h ₂	h ₃	l ₁	l ₂	s	for cabinet “U” handles
30	min.	max.	14	23	5	1,5	11	45	5,5	1,5	1,5	GN 725.1-86
30	28,6	32	16	25	6	1,5	13	51	6,5	1,5	1,5	GN 725.1-117

Specification

- Polyamide (PA)
 - glass fiber reinforced
 - temperature resistant up to 130 °C
 - black, matte
- *Plastic characteristics* → Page 1483
- **RoHS compliant**

Information

The GN 725.2 adapter allows you to install GN 725.1 cabinet “U” handles on pipes and rods with diameters ranging from 28.6 mm to 32 mm.

see also...

- *Cabinet U handles GN 725.1* → Page 85

How to order

GN 725.2-30-14-23

- 1 d₁
- 2 a
- 3 b