




Inch sizes available

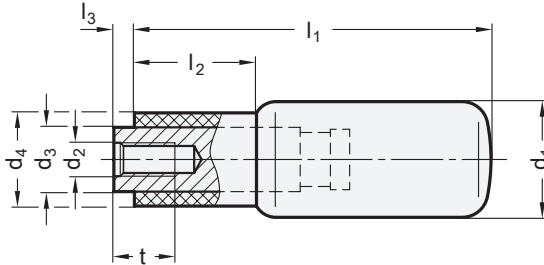

² d ₁	³ d ₂	d ₃	d ₄	l ₁	l ₂	l ₃ ≈	t
16	M 5	10	13	41,5	15	2,5	10
18	M 5	10	14,5	56	19	2,5	10
22	M 6	14	18,5	59	21	2,5	12
24	M 6	14	18,5	74	27	2,5	12
25	M 8	16	20	84	30	2,5	14

Specification

- Plastic
Technopolymer (Polyamide PA)
- temperature resistant up to 90 °C
- black, matte
- Spindle
Steel
zinc plated, blue passivated
- *Plastic characteristics* → Page 1483
- RoHS

¹ **KT**

Information

Typical in design are the revolving handles GN 798.2 with their stepped shape consisting of two cylinders giving the operator a better grip.

see also...

- *Revolving handles GN 798* → Page 32

How to order

GN 798.2-KT-24-M6

¹	Material
²	d ₁
³	d ₂