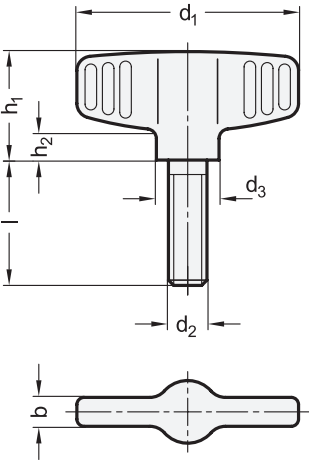


1 d₁	2 d₂	3 Length l			d₃	b	h₁	h₂
46	M 6	16	20	25	13	6	22,5	6
46	M 8	16	20	25	13	6	22,5	6
58	M 8	20	25	30	16	7	26,5	7
58	M 10	20	25	30	16	7	26,5	7

Specification

4

Stainless steel precision casting AISI CF-8

Matte shot-blasted finish

RoHS

MT

see also...	Page
GN 431 Wing Screws	QVX
GN 433 Wing Screws	QVX
GN 6335.5 Hand Knobs	QVX

Technical Information	
Stainless Steel Characteristics	QVX

How to order

1

2

3

4

1

d₁

2

d₂

3

Length l

4

Finish

1

2

3

4

GN 835-58-M10-25-MT