
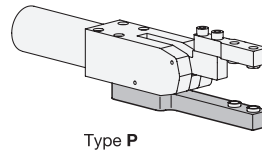


2 Type

- R** Clamping jaws at right angle to clamping arm
- P** Clamping jaws parallel to clamping arm

Mounting examples

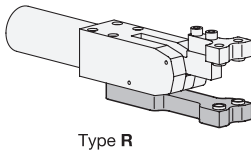

s -0,2	d ₁	d ₂ ^{HB/h6}	d ₃	d ₄ ^{HB/h6}	h	l ₁	l ₂	l ₃	l ₄	l ₅	l ₆	m ₁	m ₂	m ₃	m ₄
32	M 6	9	M 5	7	10	98,5	30	115,5	13	18,5	8	34	53	17	22
42	M 8	11	M 6	9	14	140	40	163	17	23,5	8,5	51	74,4	23	30
52	M 10	13	M 8	11	16	168	50	198	20	28	12,5	62	88,5	30	37
62	M 10	13	M 10	13	18	192,5	60	232,5	20	28	12,5	71,5	102	40	44

Specification

- Steel C45 blackened
- Socket cap screws DIN 912, centering guide bushings Steel, blackened
- *ISO-Fundamental tolerances* → Page 1479
- RoHS

Information

Holders for clamping jaws GN 869.2 have been designed for use with power clamps GN 865.

Holders for clamping jaws are equally precisely positioned on the clamping arm as are the clamping jaws GN 872 on the holders themselves.

Socket cap screws and centering guide bushings are included.

see also...

- *Power clamps GN 865* → Page 596
- *Clamping jaws GN 872* → Page 606

How to order

GN869.2-32-R

- 1 b
- 2 Type