



Type A

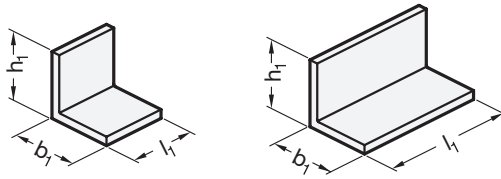

Type B

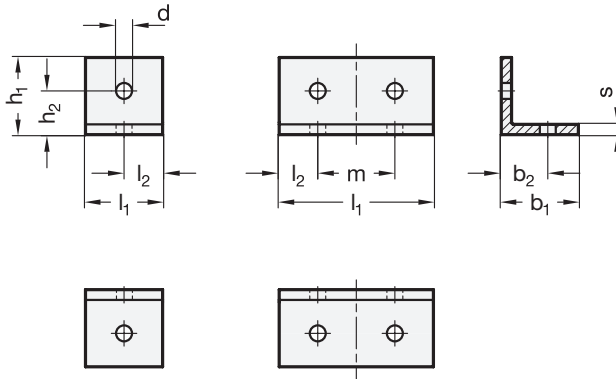

5 Type

- A without bores
- B with bores

2	3	4							
h_1	b_1	l_1	b_2	d	h_2	l_2	m	s	
30	30	30	18	6,2	18	15	-	4	
30	30	60	18	6,2	18	15	30	4	
40	40	40	24	8,2	24	20	-	5	
40	40	80	24	8,2	24	20	40	5	
50*	50	50	30	10,2	30	25	-	6	
50*	50	100	30	10,2	30	25	50	6	

* only available in version ALM

Specification

- Structural Steel drawn, with sharp edges blackened
- Aluminum pressed matte, ground
- RoHS

1

Information

STB GN 970 installation brackets are used universally for right-angle connecting and fastening of, e.g. base plates or covers.

ALM

Type A allows for the use of drilling templates specific to the application as well as fastening by welding.

Type B installation brackets have 2 or 4 holes depending on the length l_1 .

see also...

- Angle pieces, Shackles GN 967 → Page 1272

How to order

1	Material
2	h_1
3	b_1
4	l_1
5	Type

GN970-STB-40-40-80-A