


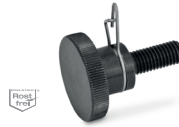

GN 420 → Page 636



GN 421 → Page 637
GN 421.10 → Page 638
GN 421.11 → Page 639
GN 421.12 → Page 639



DIN 464 → Page 647
M6 ... M10



DIN 466 → Page 646
M6 ... M12



GN 534 → Page 622



GN 534 → Page 623



GN 633 → Page 608
GN 633.1 → Page 609



GN 634 → Page 606
GN 634.1 → Page 606



GN 5334* → Page 574
GN 5334.4 → Page 575



GN 5334* → Page 575
GN 5334.4 → Page 575



GN 5337.2 → Page 560
GN 5337.7 → Page 562
Size 32 ... 63



GN 5337.2 → Page 561
GN 5337.7 → Page 563
Size 32 ... 63



GN 5337.4 → Page 564



GN 5337.4 → Page 565



DIN 6335
→ Page 582 / 586
KT / AL
Size 32 ... 63



GN 6335.4 → Page 587
GN 6335.5 → Page 587
Type ST



DIN 6336**
→ Page 540 / 544
KT / AL
Size 25 ... 63



GN 6336.4**
→ Page 545
GN 6336.5
→ Page 545
Type ST
Size 25 ... 63



GN 6336.10 → Page 548
GN 6336.11 → Page 549
GN 6336.12 → Page 549



GN 6336.3 → Page 550


* see also GN 5334.13 (with Mounted Loss Protection) → Page 576

** see also GN 6336.13 (with Mounted Loss Protection) → Page 551



Specification

Recess for retaining rings and retaining rings GN 111.6 (stainless steel) according standard sheet
→ Page 1179

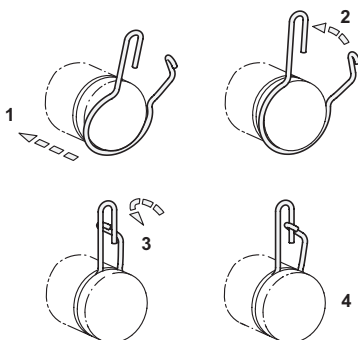

Information

The standards listed can be delivered with loss protection GN 111.7 with a recess and a retaining ring.

The retaining rings are delivered unassembled.

Ball chains GN 111 / GN 111.5 resp. retaining cables GN 111. 2 / GN 111.4 are to be ordered separately.

see also...

- Star Knobs GN 6336.13 (with Mounted Loss Protection) → Page 551
- Ball Chains GN 111 → Page 1174
- Ball Chains GN 111.5 (Stainless Steel) → Page 1174
- Retaining Cables GN 111.2 (Stainless Steel) → Page 1176
- Spiral Retaining Cables GN 111.4 → Page 1175

How to order
GN 111.7

Knurled thumb screw GN 421-M5-20
with loss protection **GN 111.7**

