


- 1

Type
- DK With triangular spindle
- VK With square spindle
- SCH With slot

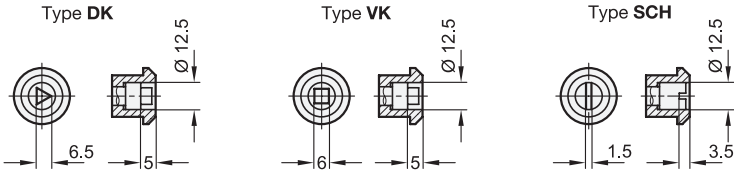

2

Latch distance A		
7,5	13,5	19,5

Specification

- Lock housing
Stainless steel AISI 303
- Latch arm
Stainless steel AISI 304
- Other parts
Stainless steel AISI 304
- Protection class IP65
- *IP Protection Classes* → Page 2153
- *Stainless Steel Characteristics* → Page 2166
- RoHS

Accessory

- Socket Keys 119.2 → Page 1266
- Protective Caps GN 120 → Page 1268

Information

Latches GN 115.6 have smaller dimensions than standard latches GN 115, making them ideal for applications with limited space or requiring an unobtrusive appearance. Thanks to the stainless steel material, the latches are optimally suited for use in harsh environments.

They lock by a turning operation limited to 90° which moves the latch arm in the locked position behind the door frame. The bevels of the latch arm ease the closing of the door.

Latch arms are available with different bend angles to cover a latch arm distance A of 7,5 / 13,5 and 19,5 mm.

The latches GN 115.6 are supplied with loosely enclosed latch arm.

see also...

- *Construction and Assembly Instructions* → Page 1211
- *List of Latch Types* → Page 1196 ff.
- *Latches GN 115.1 (Small Type, Zinc Die casting)* → Page 1210
- *Latches GN 115 (Stainless Steel, Operation with Socket Keys)*
→ Page 1207
- *Latches GN 115 (Stainless Steel, with Operating Elements)* → Page 1206
- *Latches GN 115 (Stainless Steel, Lockable)* → Page 1208

How to order	1	Type
	2	Latch distance A

GN 115.6-DK-19,5