
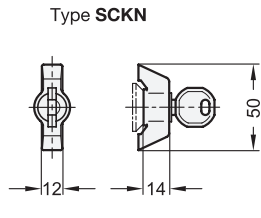


- 1 Type**
- SC** With key (same lock)
  - SCKN** With wing knob (same lock)
  - SCTN** With T-handle (same lock)
- 3 Version of the hook**
- H1** Pivoting radius R=28
- 5 Identification no.**
- 1** Without latch bracket
  - 2** With latch bracket

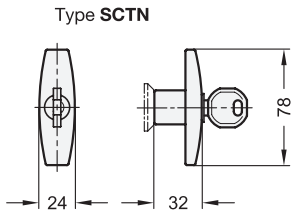

| Hook distance <b>A</b> | <b>d</b> |                  | <b>h</b> |
|------------------------|----------|------------------|----------|
|                        | Type SC  | Type SCKN / SCTN |          |
| 18                     | 28       | 32               | 6        |

\* Dimensions of the latch bracket → Page XYZ

**2**

**4**

**Specification**

**Lock housing**  
Stainless steel  
• AISI 303 for type SC  
• AISI 316 for type SCKN / SCTN

**Operating element** for type SCKN / SCTN  
Stainless steel AISI 316

**Other parts**  
Stainless steel AISI 304

**Key**  
Nickel silver with plastic handpiece

**Protection class** IP 65

RoHS

**On request**

- Hook-type latches with other hook distance A
- Hook with other pivoting radius R

Hook-type latches GN 115.8 with hook and latch bracket are mainly used for sliding doors and flaps. The locking action is in radial direction to the axis of rotation, resulting in a wide variety of different uses. The latches are delivered with 2 keys and loosely enclosed hook. The key can be removed in both end positions. Types with a standard lock allow every lock to be opened with the same key.

**see also...**

|   | Page |
|---|------|
| <b>GN 115.8</b> Hook-Type Latches (Zinc Die Casting, Lockable)              | QVX  |
| <b>GN 115.8</b> Hook-Type Latches (Stainless Steel, with Operating Element) | QVX  |

**Technical Information**

|  |     |
|--|-----|
| Construction and assembly instructions | QVX |
| Overview Latch Types                   | QVX |
| IP Protection Classes                  | QVX |
| Stainless Steel Characteristics        | QVX |

**How to order**

|                              |
|------------------------------|
| <b>1</b> Type                |
| <b>2</b> Hook distance A     |
| <b>3</b> Version of the hook |
| <b>4</b> Material            |
| <b>5</b> Identification no.  |

**GN 115.8-SCTN-18-H1-N-1**