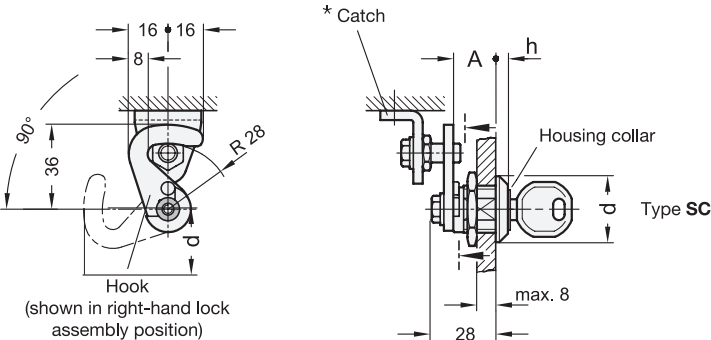


- 1

Type
- SC With key (same lock)
- SCKN With wing knob (same lock)
- SCTN With T-handle (same lock)
- 3

Version of the hook
- H1 Pivoting radius R=28
- 5

Identification no.
- 1 Without latch bracket
- 2 With latch bracket

Hook distance A	d		h
	Type SC	Type SCKN / SCTN	
18	28	32	6

* Dimensions of the latch bracket → Page XYZ

Specification	4
Lock housing	N
Stainless steel	
• AISI 303 for type SC	
• AISI 316 for type SCKN / SCTN	
Operating element for type SCKN / SCTN	
Stainless steel AISI 316	
Other parts	
Stainless steel AISI 304	
Key	
Nickel silver with plastic handpiece	
Protection class IP 65	
RoHS	
On request	
• Hook-type latches with other hook distance A	
• Hook with other pivoting radius R	

Hook-type latches GN 115.8 with hook and latch bracket are mainly used for sliding doors and flaps. The locking action is in radial direction to the axis of rotation, resulting in a wide variety of different uses. The latches are delivered with 2 keys and loosely enclosed hook. The key can be removed in both end positions. Types with a standard lock allow every lock to be opened with the same key.

see also...	Page
GN 115.8 Hook-Type Latches (Zinc Die Casting, Lockable)	QVX
GN 115.8 Hook-Type Latches (Stainless Steel, with Operating Element)	QVX

Technical Information	
Construction and assembly instructions	QVX
Overview Latch Types	QVX
IP Protection Classes	QVX
Stainless Steel Characteristics	QVX

How to order	
1	Type
2	Hook distance A
3	Version of the hook
4	Material
5	Identification no.
GN 115.8-SCTN-18-H1-N-1	