


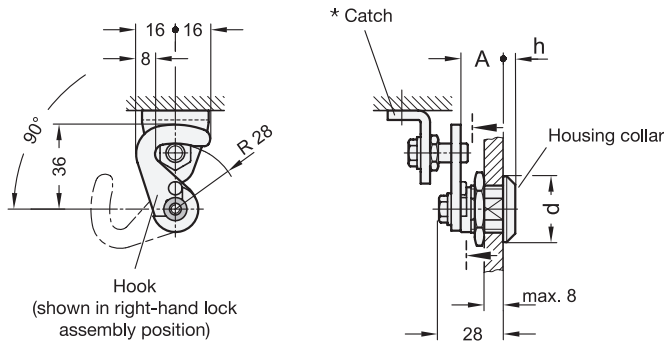

- 1

Type
- SG

With star knob
- KGN

With wing knob
- HGN

With lever
- SKN

With wing knob
- STN

With T-handle
- 3


Version of the hook
- H1

Pivoting radius R=28
- 5

Identification no.
- 1

Without latch bracket
- 2

With latch bracket

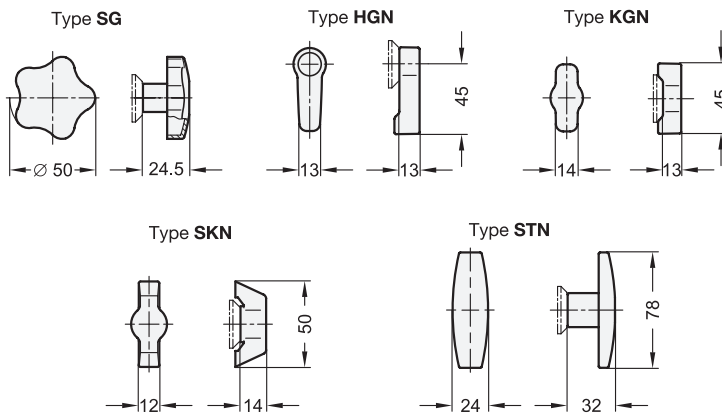

Hook distance A	d		h	
	Type SG / KGN / HGN	Type SKN / STN	Type SG / KGN / HGN	Type SKN / STN
18	28	32	4	6

* Dimensions of the latch bracket → Page XYZ

Specification

4

Lock housing

Stainless steel

• AISI 303 for type SG / KGN / HGN

• AISI 316 for type SKN / STN

N

Operating element

• Stainless steel AISI 304 for type SG

Sheet metal drawn / Hub welded

• Stainless steel AISI CF-8 for type KGN / HGN

• Stainless steel AISI 316 for type SKN / STN

Other parts

Stainless steel AISI 304

RoHS

On request

• Hook-type latches with other hook distance A

• Hook with other pivoting radius R

Hook-type latches GN 115.8 with hook and catch are mainly used for sliding doors and flaps. The locking action is in radial direction to the axis of rotation, resulting in a wide variety of different uses. The hook-type latches GN 115.8 are supplied with loosely enclosed hook.

see also...

GN 115.8 Hook-Type Latches (Zinc Die Casting, with Operating Element)

PageQVX

Technical Information

Construction and assembly instructions

QVX

Overview Latch Types

QVX

Stainless Steel Characteristics

QVX

How to order

1 2 3 4 5

GN 115.8-HGN-18-H1-N-1

1

Type

2

Hook distance A

3

Version of the hook

4

Material

5

Identification no.