


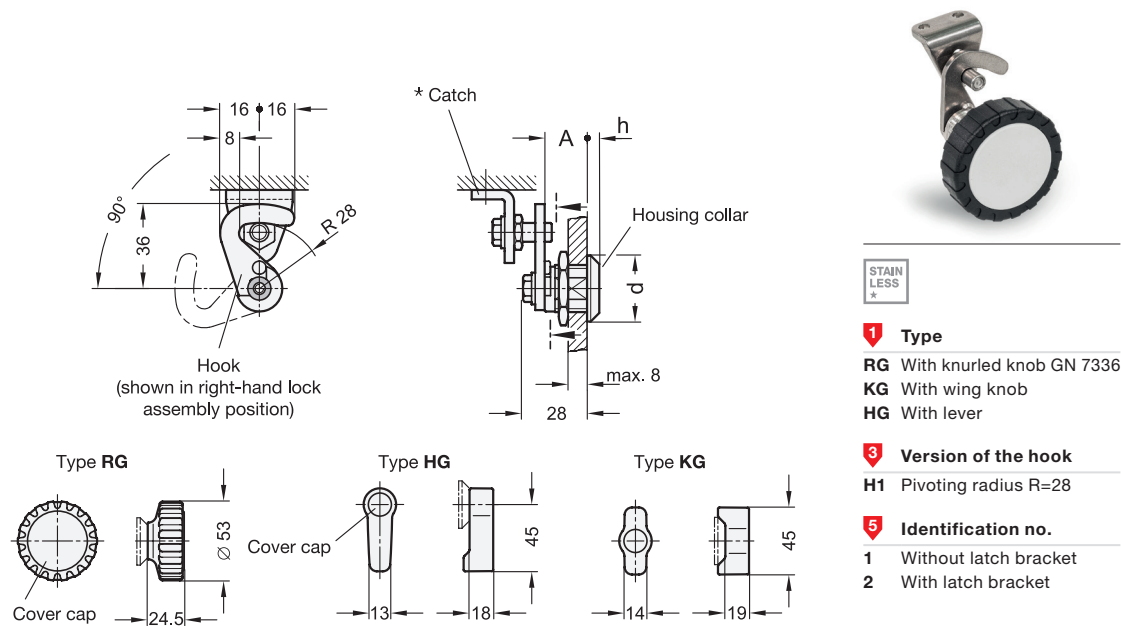

Hook distance A	d	h
18	28	4

* Dimensions of the latch bracket → Page XYZ

Specification	4
Lock housing	N
Stainless steel AISI 303	
Operating element	
Plastic, Polyamide (PA)	
Black, matte finish	
Other parts	
Stainless steel AISI 304	
Cover cap	
Plastic	
Light gray, matte finish	
Protection class IP 65	
RoHS	
On request	
• Hook-type latches with other hook distance A	
• Hook with other pivoting radius R	

Hook-type latches GN 115.8 with hook and catch are mainly used for sliding doors and flaps. The locking action is in radial direction to the axis of rotation, resulting in a wide variety of different uses.

The hook-type latches GN 115.8 are supplied with loosely enclosed hook.

see also...	Page
GN 115.8 Hook-Type Latches (Stainless Steel, with Operating Element)	QVX
GN 115.8 Hook-Type Latches (Stainless Steel, Operation with Key)	QVX
GN 115.8 Hook-Type Latches (Stainless Steel, Lockable)	QVX

Technical Information	
Construction and assembly instructions	QVX
Overview Latch Types	QVX
IP Protection Classes	QVX
Plastic Characteristics	QVX
Stainless Steel Characteristics	QVX

How to order	1 Type
	2 Hook distance A
	3 Version of the hook
	4 Material
	5 Identification no.
GN 115.8-RG-18-H1-N-2	