


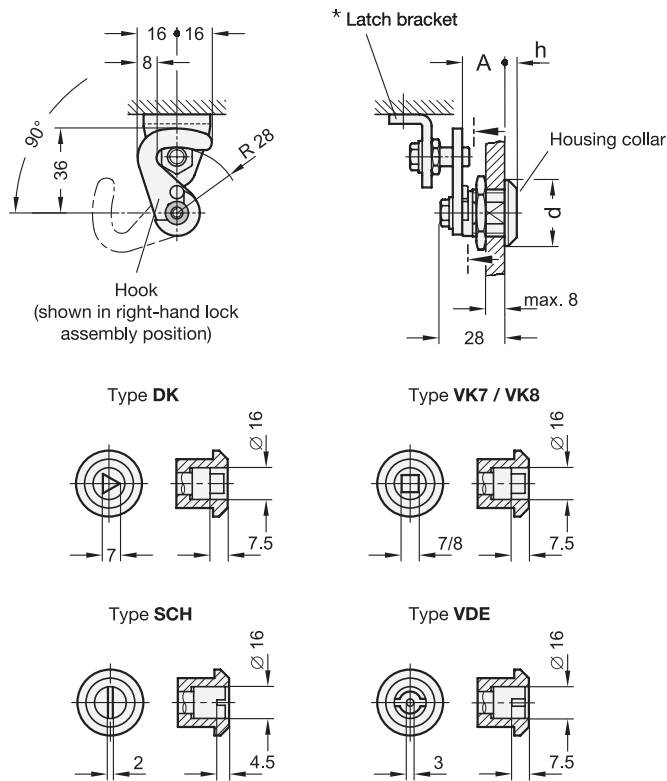

- STAINLESS

*
- 1

Type

DK With triangle

VK7 With square

VK8 With square

SCH With slot

VDE With double bit
- 3

Version of the hook

H1 Pivoting radius R=28
- 5

Identification no.

1 Without latch bracket

2 With latch bracket

Hook distance A	d	h
18	28	4

* Dimensions of the latch bracket → Page XYZ

Specification	4
Lock housing	
Stainless steel AISI 303	N
Other parts	
Stainless steel AISI 304	
Protection class IP 65	
RoHS	
On request	
• Hook-type latches with other hook distance A	
• Hook with other pivoting radius R	
Accessory	Page
GN 119.2 Socket Keys	QVX
GN 120 Protective Caps	QVX
GN 120.1 Opening Handles	QVX

Hook-type latches GN 115.8 with hook and latch bracket are mainly used for sliding doors and flaps. The locking action is in radial direction to the axis of rotation, resulting in a wide variety of different uses.

The hook-type latches GN 115.8 are supplied with loosely enclosed hook.

see also...

Page

GN 115.8 Hook-Type Latches (Operation with Stainless Steel-Operating Element)

QVX

GN 115.8 Hook-Type Latches (Zinc Die Casting, Operation with Operating Element)

QVX

Technical Information	
Construction and assembly instructions	QVX
Overview Latch Types	QVX
IP Protection Classes	QVX
Stainless Steel Characteristics	QVX

How to order	1 Type
	2 Hook distance A
	3 Version of the hook
	4 Material
	5 Identification no.

1

2

3

4

5

GN 115.8-VK8-18-H1-N-1