


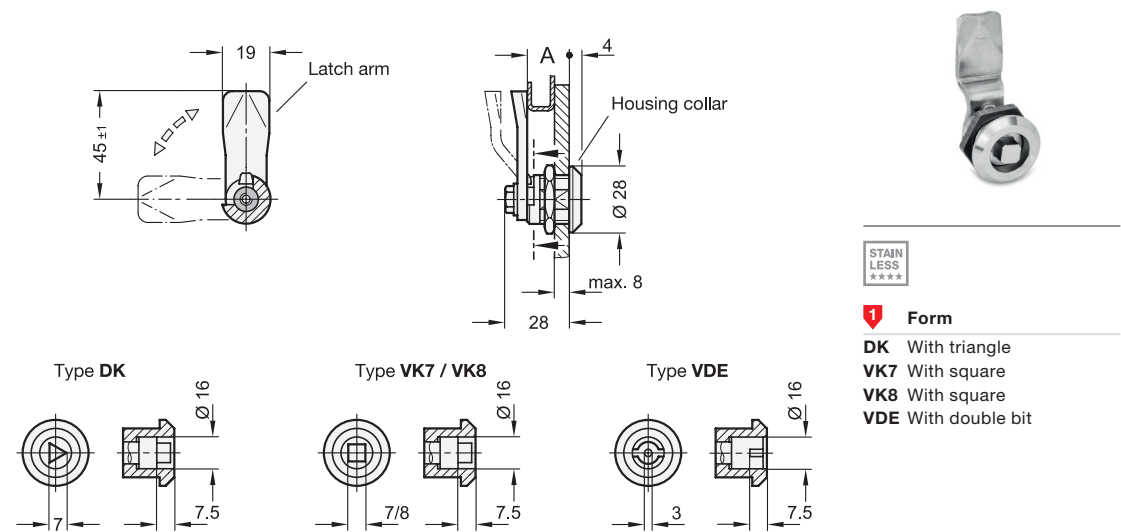

2

| Latch distance A |    |    |    |    |    |    |    |    |
|------------------|----|----|----|----|----|----|----|----|
| 6                | 10 | 14 | 18 | 20 | 22 | 24 | 26 | 28 |

3

| Specification                 |    |
|-------------------------------|----|
| Lock housing                  | A4 |
| Stainless steel<br>AISI 316Ti |    |
| Latch arm                     |    |
| Stainless steel AISI 316      |    |
| Other parts                   |    |
| Stainless steel AISI 316      |    |
| Protection class IP 66        |    |
| RoHS                          |    |
| On request                    |    |
| • Other operations            |    |

Latches GN 115 lock by a turning operation limited to 90° which moves the latch arm in the locked position behind the door frame. The bevels of the latch arm ease the closing of the door. Thanks to the stainless steel material, the latches are optimally suited for use in highly corrosive environments. Latch arms are available with different bend angles to cover a latch arm distance A from 6 to 28 mm. Latches GN 115 are supplied with loosely enclosed latch arm.

| see also...                                        | Page |
|----------------------------------------------------|------|
| GN 115 Latches (Operation with Socket Key)         | QVX  |
| GN 115 Latches (Operation with Operating Elements) | QVX  |

| Technical Information                  |     |
|----------------------------------------|-----|
| Construction and Assembly Instructions | QVX |
| Overview of Latch Types                | QVX |
| IP Protection classes                  | QVX |
| Stainless Steel Characteristics        | QVX |

| Accessory                                  |                |
|--------------------------------------------|----------------|
| GN 120.4 Electromechanical Locking Systems | QVX            |
| GN 123 Sheet Metal Punches                 | QVX            |
| GN 120 Protective Caps                     | ganternorm.com |
| GN 120.1 Opening Handles                   | ganternorm.com |
| GN 120.2 Protective Guide Plates           | ganternorm.com |
| GN 120.3 Internal Handles                  | ganternorm.com |

| How to order |                  |
|--------------|------------------|
| 1            | Form             |
| 2            | Latch distance A |
| 3            | Material         |

GN 115-DK-18-A4