



3 Type

- A** Mounting with countersunk screw
- B** Mounting with adhesive pad

Mounting hole pattern

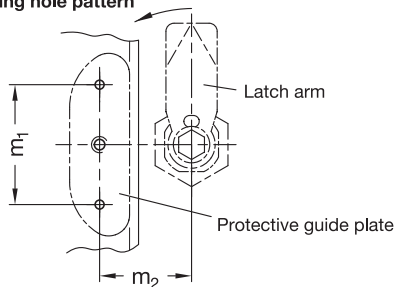

Application example

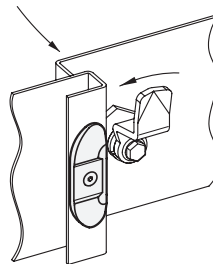

1

2

h	b₁	b₂	d₁	d₂	l₁	l₂	m₁	m₂ ±2	useable for
60	4	4,6	M 4	3	20	10	40	35	GN 115 / GN 115.7 / GN 115.9 / GN 115.10 / GN 515

Specification

- Plastic (Polyamide PA)
Black, matte finish
- Adhesive pad (only type B)
Scotch-Mount™ 4026
Double-sided,
with polyurethane foam backing
- *Plastic Characteristics* → Page 2158
- RoHS

4

● SW

Information

Protective guide GN 120.2 plates are used in connection with door latches, using the principle of friction. They prevent the latch arm from causing abrasion, for example to corrosion protection layers on a door frame. They additionally prevent unintended opening, as the latch arms lock into a small recess in their closed position.

If the d₂ positioning tabs are not required they can easily be removed with side cutting pliers, for example.

see also...

- *List of Latch Types* → Page 1196 ff.
- *Protective Caps GN 120* → Page 1268
- *Internal Cabinet Handles GN 120.3* → Page XYZ

How to order

GN 120.2-60-4-A-SW

1	h
2	b₁
3	Type
4	Color