


Assembly / profile machining




3 Type

V With anti-twist protection

4 Coding

D With 2 screws and double T-nut

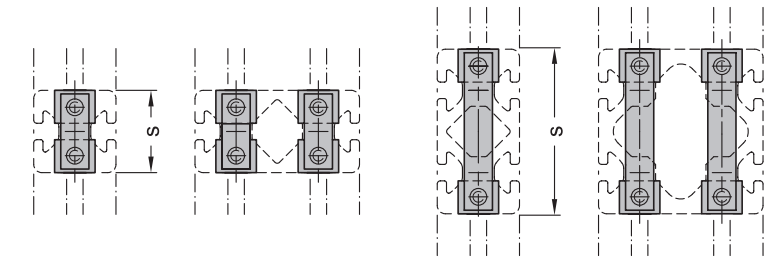

s	n	Bundle Pieces	d <sub>1</sub>	d <sub>2</sub>	l <sub>1</sub>	l <sub>2</sub>	m <sub>1</sub>	m <sub>2</sub> +0,5	A/F	t +0,5	Tightening torque in Nm
30	6	2	16	M 6	25,5	28	17	15	4	12,7	8
40	8	2	20	M 8	33,5	36	24	20	5	16	25
60	6	2	16	M 6	25,5	58	47	15	4	12,7	8
80	8	2	20	M 8	33,5	76	64	20	5	16	25

Specification		5	6
<b>Housing</b>			
Zinc die casting			
Zinc plated	ZZ		
<b>Screws / T-nut</b>			
Steel			
Zinc plated, blue passivated	SZ		
RoHS			

Universal connectors GN 22i fasten aluminum profiles at right angles and secure them against twisting. Only one profile has to be machined. The connection can be freely positioned and slid along the slot. If panels are used in the slot, they must be suitably pocketed. Universal connectors are supplied in bundles. The table shows the quantity included in each bundle.

see also...	Page
GN 22i Universal Connectors (With Single T-Nut)	QVX
GN 10i Aluminum Profiles (Profile Type Light)	QVX
GN 10i Aluminum Profiles (Profile Type Heavy)	QVX

Technical Information	
Assembly Instructions	QVX

How to order	
1 s	
2 n	
3 Type	
4 Coding	
5 Material / Finish (Housing)	
6 Material / Finish (Screws / T-nut)	
7 Bundle	
GN 22i-606-V-D-ZZSZ-2	