


Application example

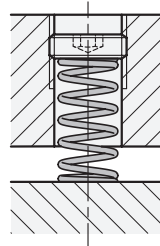

- 2** Type
- A** Without thread coating
 - PRB** With thread coating (polyamide allround coating)



d	GN 252.5	h	A/F
M 12 x 1,5	M 12 x 1,5	10	6
M 16 x 1,5	M 16 x 1,5	10	8
M 20 x 1,5	M 20 x 1,5	12	10
M 24 x 1,5	M 24 x 1,5	12	14
M 27 x 1,5	M 27 x 1,5	12	14
M 30 x 1,5	-	12	17
M 33 x 1,5	-	12	17

Specification

GN 252

Steel

- Hardened
- Blackened

GN 252.5

Stainless steel 1.4305

RoHS

The thread locking PRB (polyamide allround coating) is a clamping lock which prevents the locking screw from being inadvertently being loosened and becoming detached.

see also...

	Page
GN 749 Threaded Plugs (with Sealing Ring Rubber)	QVX
DIN 906 Threaded Plugs (with Conical Thread)	QVX
DIN 908 Threaded Plugs	QVX

Technical Information

Stainless Steel Characteristics	QVX
---------------------------------	-----

How to order (Steel)

GN 252-M24x1,5-A	1 d
	2 Type

How to order (Stainless Steel)

GN 252.5-M24x1,5-PRB	1 d
	2 Type

