

4 Type
A Without accessory

1 s		2 Length l		3 n	d	h ₁	k
Nominal dimension	Actual dimension	Nominal dimension	Actual dimension		For screw		
30	30	30	30	6	M 6	2,5	-
30	30	60	60	6	M 6	3,5	-
40	40	40	40	8	M 8	5	-
40	40	80	80	8	M 8	5	-
80	74	80	76	8	M 8	8	40

Specification

- Angle bracket
- Zinc die casting
- Painted, white aluminum

5

ZW

Accessory

- T-Nuts GN 50i → Page QVX

Information

Angle brackets GN 30i fasten aluminum profiles to objects such as tables and panels or at right angles to each other. Machining of the profile is not necessary.

The connection can be freely positioned and slid along the slot. To fasten the angle brackets to a panel or transversely to an aluminum profile, the guide steps must be broken off.

see also...

- Aluminum Profiles GN 10i (Profile Type Light) → Page QVX
- Aluminum Profiles GN 10i (Profile Type Heavy) → Page QVX
- Aluminum Profiles GN 11i (with Partially Closed Slots) → Page QVX

How to order


GN 30i-40408-A-ZW

1	s
2	Length l
3	n
4	Type
5	Finish




Assembly Options / Application Examples

Assembly of cover cap

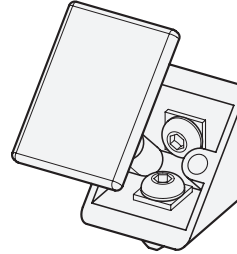

Use

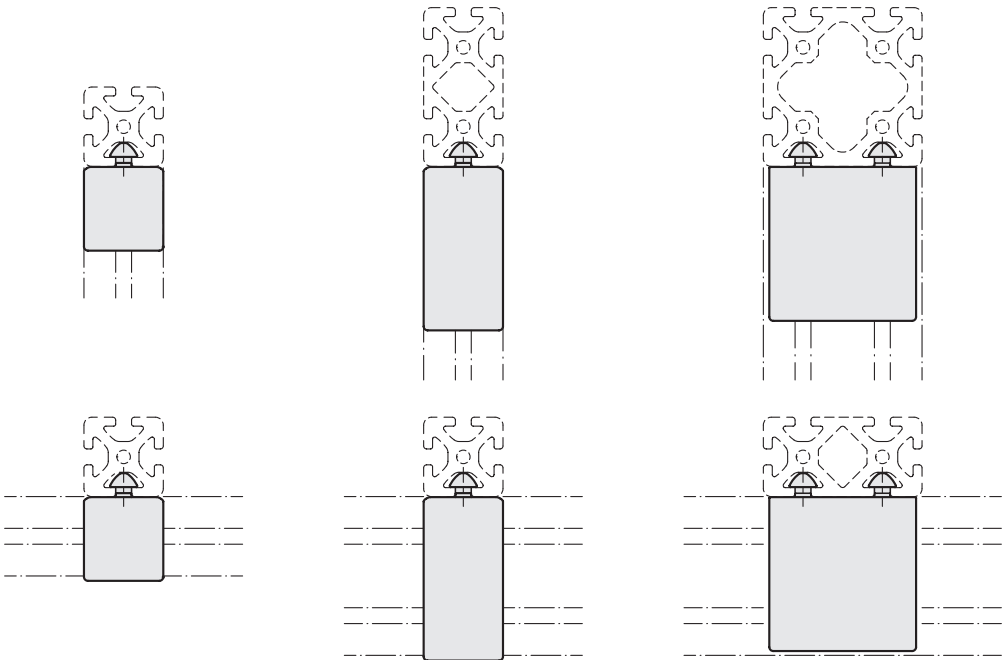

Application examples

