


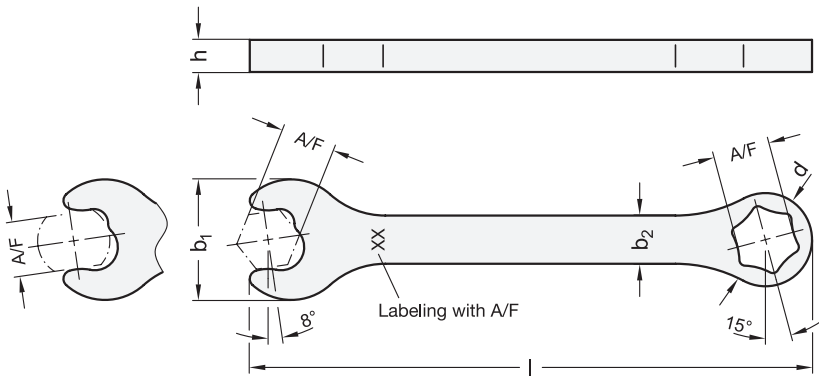

- 1 Coding**
- RM** Open-ended combination wrench
- 3 Type**
- SF** Hex, flat

A/F	b ₁ ≈	b ₂ ≈	d ≈	h	Length l ≈
7	15	6	12	5	100
8	17	7	13	5	105
10	21	9	16	5	125
11	23	9,5	18	5	135
13	27	11	21	5	150
14	30	12	23	5	155
15	32	16	24	6	160
16	33	14	26	6	165
17	36	15	28	6	170
18	38	15	29	6	175
19	40	17	31	6	180
22	46	19	36	8	185
24	50	21	39	8	200
27	56	23	44	8	220
30	63	26	48	10	240

Specification	4	5
Aluminum	AL	
Matte finish		M
• Tumbled for A/F 7 ... A/F 19		
• Chamfered for A/F 22 ... A/F 30		
RoHS		
Technical Information	Page	
Product Family Hygienic Design	QVX	

Combination wrenches GN 3113 are used to assemble and adjust Hygienic Design standard parts with two or six wrench flats.

In conjunction with the aluminum material used, the rounded geometry of the wrench surfaces transfers the torque to the screw head without causing damage.

The combination wrenches are designed for manual operation with moderate torques.

see also...	Page
GN 1580 Screws / Nuts (Stainless Steel, Hygienic Design)	QVX
GN 1581 Screws (Stainless Steel, Low-Profile Head, Hygienic Design)	QVX
GN 1582 Screws (Stainless Steel, with Recessed Stud, Hygienic Design)	QVX
GN 1150 Latches (Stainless Steel, Full Hygiene, Hygienic Design)	QVX
GN 19 Leveling Feet (Stainless Steel, Foot Plate Sheet Metal, Hygienic Design)	QVX
GN 20 Leveling Feet (Stainless Steel, Hygienic Design)	QVX
GN 20.1 Cover Sleeves (Stainless Steel, Hygienic Design)	QVX
GN 8170 Indexing Plungers (Stainless Steel, Front- / Full Hygiene, Hygienic Design)	QVX
GN 3124 Sockets (for Hygienic Design Standard Parts)	QVX

How to order	1 Coding
	2 A/F
	3 Type
	4 Material
	5 Finish
GN 3113- ¹ RM- ² 16- ³ SF- ⁴ AL ⁵ M	