

**4 Profile type**

S Heavy


**5 Identification no.**

1 Corner installation

**6 Type**

A Without fastening set

**Assembly / profile machining**

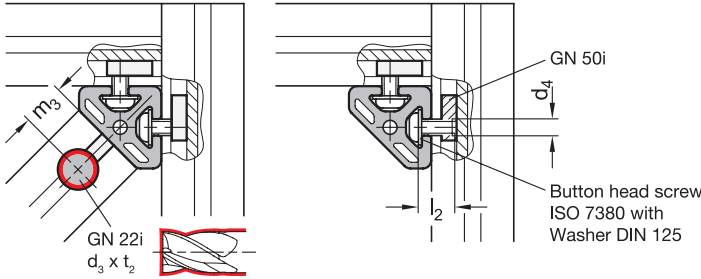

- 1
- 2
- 3

s	l <sub>1</sub>	n	d <sub>1</sub>	d <sub>2</sub>	d <sub>3</sub>	d <sub>4</sub>	h	l <sub>2</sub>	m <sub>1</sub>	m <sub>2</sub>	m <sub>3</sub> +0,5	t <sub>1</sub>	t <sub>2</sub> +0,5
30	30	6	M 6	5,5	16	M 6	27,4	12	17,4	-	15	6,5	12,7
40	40	8	M 8	6,5	20	M 8	36,6	16	24	-	20	14	16
60	30	6	M 6	5,5	16	M 6	27,4	12	47,4	30	15	6,5	12,7
80	40	8	M 8	6,5	20	M 8	36,6	16	64	40	20	14	16

**Specification**

- Aluminium Anodized, natural color

• RoHS



N

**Accessory**

- Universal Connectors GN 22i → Page QVX
- T-Nuts GN 50i → Page QVX

**Information**

Angle connectors GN 32i fasten aluminum profiles together at right angles and are primarily used for creating corner braces at 45° angles.

The braces are fastened with universal connectors GN 22i, requiring their anti-twist protection to be removed. This requires the profile to be machined.

see also...

- Aluminum Profiles GN 10i (Profile Type Light) → Page QVX
- Aluminum Profiles GN 10i (Profile Type Heavy) → Page QVX
- Aluminum Profiles GN 11i (with Partially Closed Slots) → Page QVX

**How to order**

1	s
2	l <sub>1</sub>
3	n
4	Profile type
5	Identification no.
6	Type
7	Finish

**GN 32i-80408 S-1-A-N**



### Assembly Instructions / Profile Machining

