
 
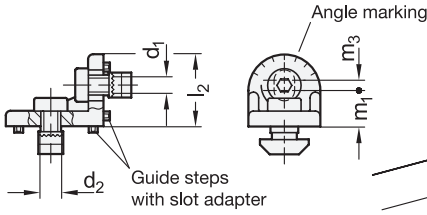



$l_1 = 28$

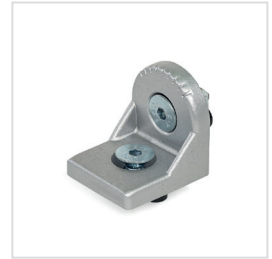





 
Assembly

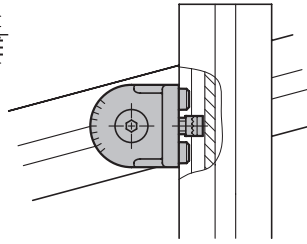

4 Type

C With fastening set

$l_1 = 40$

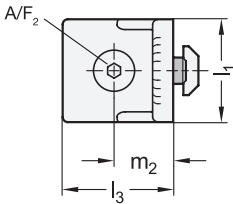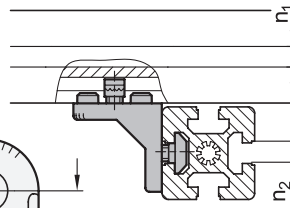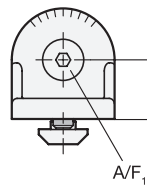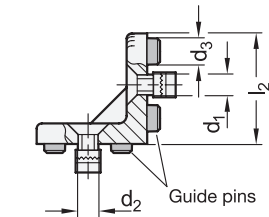

1 2 3

l_1	n_1	n_2	d_1	d_2	d_3	l_2	l_3	m_1	m_2	m_3	m_4	A/F ₁	A/F ₂	Grid size
28	10	10	M 8	M 8	-	28	38	14,5	14,5	3,5	13	5	5	40 / 45
40	10	10	M 8	M 8	10	42,5	42,5	22,5	22,5	-	-	5	5	45

Specification

5 6

- Housing
Aluminum
Painted, white aluminum **AW**
- Fastening set
Screws and T-slot nuts
Steel, zinc plated, blue passivated **SZ**
- Slot adapter (for $l_1 = 28$)
Plastic
- Guide pins (for $l_1 = 40$)
Plastic
- RoHS

Information

Rotating angle brackets GN 41b connect two crossed aluminum profiles at any angle. Machining of the profile is not necessary.

Depending on the installation situation for the rotating angle bracket, it may be necessary to break off the guide steps or leave out the guide pins.

see also...

- Aluminum Profiles GN 10b (Profile Type Light) → Page QVX
- Aluminum Profiles GN 10b (Profile Type Heavy) → Page QVX

How to order

1	l_1
2	n_1
3	n_2
4	Type
5	Finish (Housing)
6	Material / Finish (Fastening set)

GN 41b-401010-C-AWSZ

3.1

3.2

3.3

3.4

3.5

3.6

3.7

3.8

3.9

