


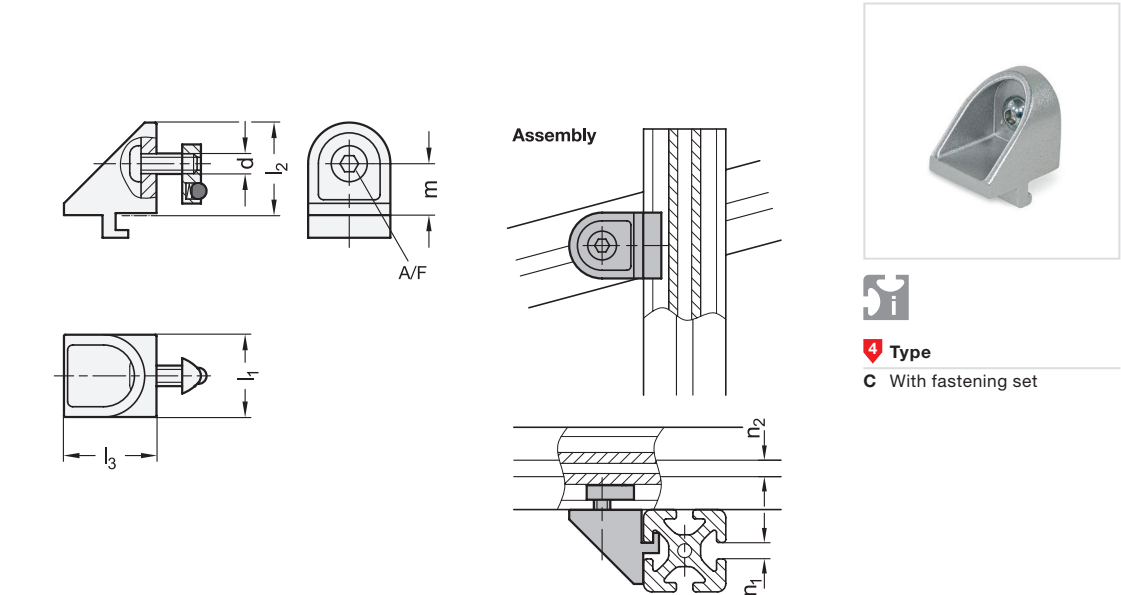

1 l₁	2 n₁	3 n₂	d	l₂	l₃	m	A/F
24	6	6	M 6	27	27	15	4
32	8	8	M 8	36	36	20	5

Specification	5	6
• Housing Zinc die casting Painted, white aluminum		ZW
• Fastening set Screw and T-nut Steel, zinc plated, blue passivated		SZ
• RoHS		

Information

Rotating angle brackets GN 42i connect two crossed profiles at any angle. Machining of the profile is not necessary.

Loosening the screw simultaneously adjusts the angle and position along the grooves.

see also...

• Aluminum Profiles GN 10i (Profile Type Light) → Page QVX

• Aluminum Profiles GN 10i (Profile Type Heavy) → Page QVX

• Aluminum Profiles GN 11i (with Partially Closed Slots) → Page QVX

How to order	1	l ₁
	2	n ₁
	3	n ₂
	4	Type
	5	Finish (Housing)
	6	Material / Finish (Fastening set)

1

2

3

4

5

6

GN 42i-3288-C-ZWSZ