
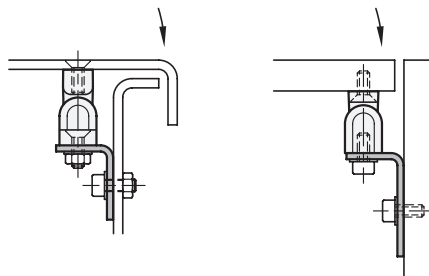


**Application examples**

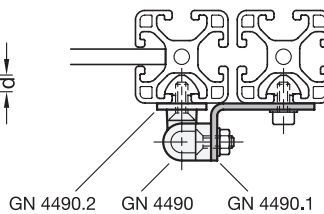

**3 Type**

L L-shaped

**4 Identification no.**

- 1 Short
- 2 Long

**2**

l <sub>1</sub>	d	l <sub>2</sub>		l <sub>3</sub>	m <sub>1</sub>	m <sub>2</sub>		m <sub>3</sub>		m <sub>4</sub>	m <sub>5</sub>	s	For aluminum profiles with grid size	
		ld. no. 1	ld. no. 2			ld. no. 1	ld. no. 2	ld. no. 1	ld. no. 2				ld. no. 1	ld. no. 2
50	4,2	22	33,5	18,5	40	9,5	11	7	15,5	8,9	5	2	20	30
68	4,2	32	51	21,5	55	11	11	14	33	9,5	7	2	30	40 / 45
80	5,2	-	49	24,5	65	-	11	-	31	11,5	7	2	-	40 / 45

**Specification**

Stainless steel AISI 316  
Matte shot-blasted

**1**

A4

**5**

GS

RoHS

Mounting plates GN 4490.1 enable the use of ball catches GN 4490 in various installation situations. The positioning is facilitated by slotted holes.

see also...

	Page
GN 4490 Ball Catches	QVX
GN 4490.2 Mounting Plates (for Mounting Blocks)	QVX

**Technical Information**

Stainless Steel Characteristics	QVX
---------------------------------	-----

**Accessory**

GN 50b T-Nuts	QVX
GN 50i T-Nuts	QVX
GN 51b T-Slot Nuts	QVX

How to order

<b>1</b> Material
<b>2</b> l <sub>1</sub>
<b>3</b> Type
<b>4</b> Identification no.
<b>5</b> Finish

**GN 4490.1-A4-68-L-1-GS**

3.1  
3.2  
3.3  
3.4  
3.5  
3.6  
3.7  
3.8  
3.9  
3.10

