


**3** Type  
F Flat

**Assembly instruction**

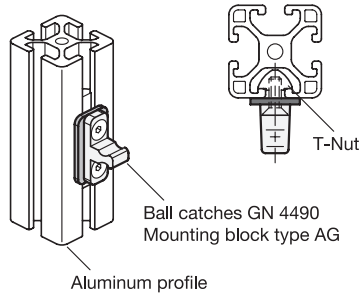

**2**

$l_0$ Length of ball catch	$d$	$l_1$	$l_2$	$m$	$s$	For aluminum profiles with grid size
50	4,5	30	16	17	2	20 / 30 / 40 / 45
68	4,5	32,5	17	20	2	20 / 30 / 40 / 45
80	5,5	40	20	25	2	20 / 30 / 40 / 45

**Specification**

Stainless steel AISI 316  
Matte shot-blasted

**1**

**A4**

**4**

**GS**

RoHS

Mounting plates GN 4490.2 enlarge the contact surface of the mounting blocks of ball catches GN 4490. This allows mounting blocks to be securely attached to aluminum profiles regardless of the slot width.

**See also...**

	Page
GN 4490 Ball Catches	QVX
GN 4490.1 Mounting Plates (for Ball Housings)	QVX

**Technical Information**

Stainless Steel Characteristics	QVX
---------------------------------	-----

**Accessory**

GN 50b T-Nuts	QVX
GN 50i T-Nuts	QVX
GN 51b T-Slot Nuts	QVX

**How to order**

<b>1</b> Material
<b>2</b> $l_0$
<b>3</b> Type
<b>4</b> Finish

**GN 4490.2-A4-50-F-GS**

3.1  
3.2  
3.3  
3.4  
3.5  
3.6  
3.7  
3.8  
3.9  
3.10

