


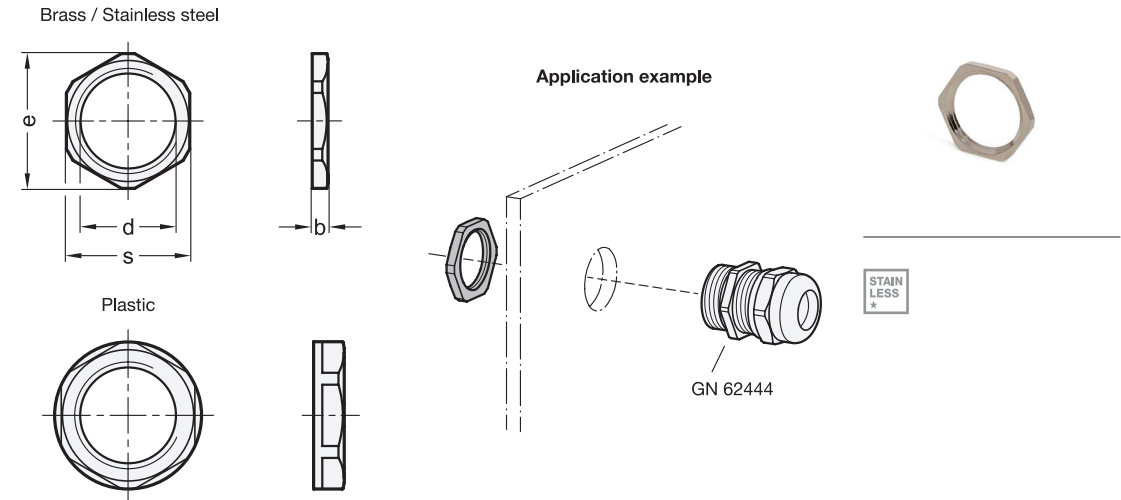

1

d	b			e ≈			s		
	MS	NI	KLG	MS	NI	KLG	MS	NI	KLG
M 12 x 1,5	2,8	2,8	5	16,3	16,3	19,3	15	15	18
M 16 x 1,5	2,8	3	5	20,9	20,9	24,2	19	19	22
M 20 x 1,5	3	3,5	6	26,2	26,6	28,6	24	24	26
M 25 x 1,5	3,5	4	6	31,7	32,7	35	29	30	32
M 32 x 1,5	4	5	7	39,5	38,7	45,9	36	36	41
M 40 x 1,5	5	5	7	50,4	49,6	55,7	46	46	50
M 50 x 1,5	5	5	8	58,5	59,5	65,7	57	55	60
M 63 x 1,5	6	6	8	76,6	76,6	82,3	70	70	75

2

Specification	
Brass	MS
Nickel-plated	
Stainless steel AISI 303	NI
Plastic, polyamide (PA)	
• Glass fiber reinforced	
• Operating temperature -40 °C to +100 °C	
• Gray, RAL 7035	

RoHS

Technical Information	
Plastic Characteristics	QVX
Stainless Steel Characteristics	QVX

see also...

	Page
GN 62444.1 Mounting Nuts (PG Thread)	QVX
GN 62444 Cable Glands (Metric Thread)	QVX
GN 62444.2 Threaded Plugs (Metric Thread)	QVX
GN 62444.4 Reducers (Metric Thread)	QVX

How to order

1	d
2	Material

GN62444.1-M25x1,5-MS