


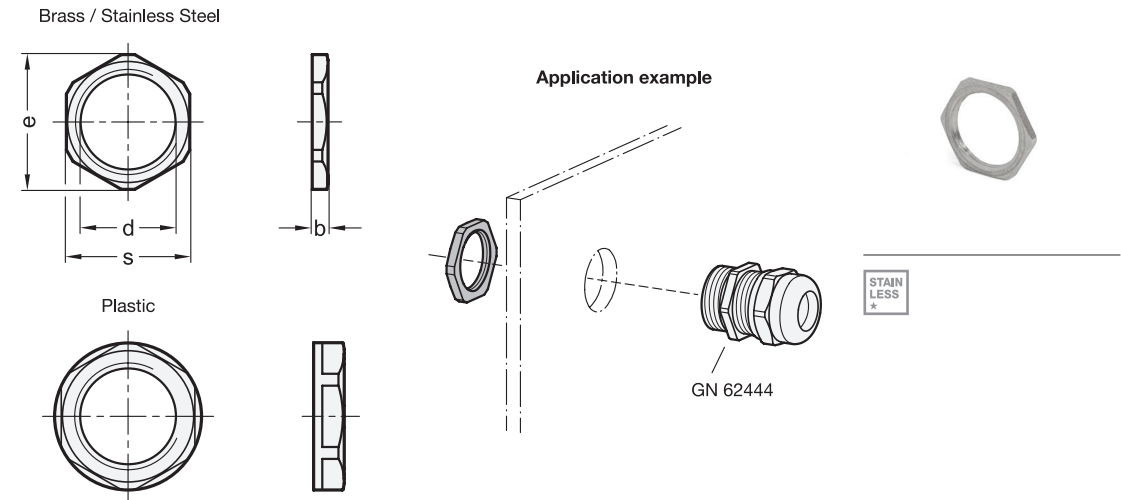

d			b			e ≈			s		
MS	NI	KLK	MS	NI	KLK	MS	NI	KLK	MS	NI	KLK
PG 7	PG 7	PG 7	2,8	2,8	5	16,5	15,4	20,9	15	14	19
PG 9	PG 9	PG 9	2,8	2,8	5	19,9	20,9	24,1	18	19	22
PG 11	PG 11	PG 11	3	3	5	23,4	23,9	26	21	22	24
PG 13,5	PG 13,5	PG 13,5	3	3	6	25,4	26,3	29	23	24	27
PG 16	PG 16	PG 16	3	3	6	28,9	29,6	33,2	26	27	30
PG 21	PG 21	PG 21	3,5	3,5	7	35,4	35,7	39	32	32	36
PG 29	PG 29	PG 29	4	4	7	45	45,5	50	41	41	46
PG 36	PG 36	PG 36	5	5	8	57	65,9	66,1	51	60	60
PG 42	-	PG 42	5	-	8	64,7	-	73,3	60	-	65
PG 48	-	PG 48	5,5	-	8	69	-	78,5	64	-	70

Specification	
Brass	MS
Nickel-plated	
Stainless steel AISI 303	NI
Plastic, polyamide (PA)	KLK
• Glass fiber reinforced	
• Operating temperature -40 °C to +100 °C	
• Gray, RAL 7035	
RoHS	

Mounting nuts GN 62444.1 are used for fastening cable glands, reducers or threaded plugs in through holes in enclosures.	
see also...	Page
GN 62444.1 Mounting Nuts (Metric Thread)	QVX
GN 62444 Cable Glands (PG Thread)	QVX
Technical Information	
Plastic Characteristics	QVX
Stainless Steel Characteristics	QVX

How to order	
1	d
2	Material
GN62444.1-PG13,5-NI	