

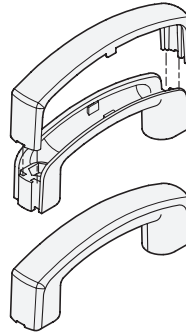


Bore for hex head screw  
DIN 931 / ISO 4014

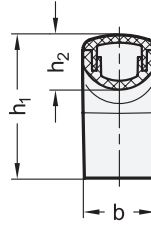

elesa  
Original design EMPC.

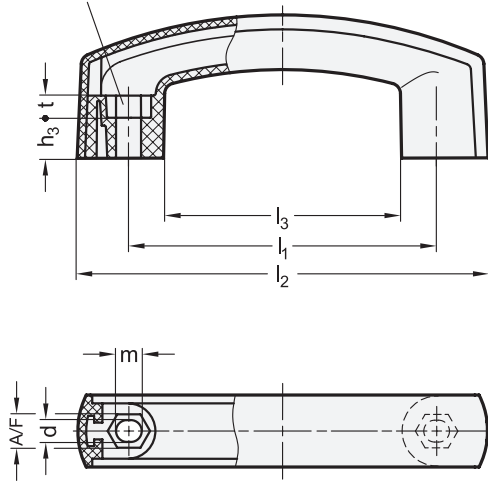

**3 Type**

**B** Mounting from the operator's side

1

2

l <sub>1</sub>		d	b	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	l <sub>2</sub>	l <sub>3</sub>	m	A/F	t
Nominal size	Actual size										
117	118,5 ±1	6,5	28	54,5	21	17,5	159,5	93	8	10	6,5
117	118,5 ±1	8,5	28	54,5	21	15,5	159,5	93	10	13	8,5

**Specification**

- Handle  
Plastic, Polyamide (PA)  
- Glass fiber reinforced  
- Temperature resistant up to 130 °C  
- Black-gray, matte finish similar to RAL 7021
- Cover cap  
Plastic, Polyamide (PA)  
- Black-gray, RAL 7021, matte finish ● **DSG**  
- Orange, RAL 2004, matte finish ● **DOR**  
- Gray, RAL 7035, matte finish ● **DGR**  
- Yellow, RAL 1021, matte finish ● **DGB**  
- Blue, RAL 5024, matte finish ● **DBL**  
- Red, RAL 3000, matte finish ● **DRT**  
- Green, RAL 6017, matte finish ● **DGN**
- *Strength Properties* → Page QVX
- *Plastic Characteristics* → Page QVX
- RoHS

4

**Information**

The design of the cabinet U-handles GN 629 matches the product family of Ergostyle®.

A typical field of application for these U-handles is doors of protective enclosures on machines and fixtures.

By attaching the cover cap, the two fastening screws are covered. It can be removed using a screwdriver.

The cover caps are supplied loose.

see also...

- *Product Family Ergostyle®* → Page QVX
- *Product Family Standard Parts for Profile Systems* → Page QVX
- *Cabinet U-Handles GN 528 (Plastic)* → Page QVX
- *Cabinet U-Handles GN 628 (Plastic)* → Page QVX
- *Cabinet U-Handles GN 565.1 (Aluminum)* → Page QVX

How to order

1	l <sub>1</sub> (Nominal size)
2	d
3	Type
4	Color of the cover cap

GN 629-117-6,5-B-DSG

