



elesa
Original design MPG-V / MPG-P

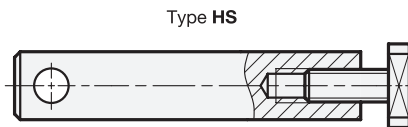


1 Type

- H** Retaining rod with internal thread
- HA** Retaining rod with threaded stud
- S** Screw with T-head
- HS** Retaining set

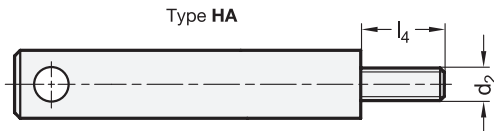

Application example

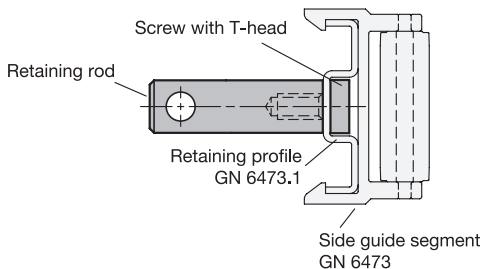

2

d ₁			d ₂		d ₃	d ₄	l ₁	l ₃	l ₄	A/F	t
Type H / HA / HS			Type H / S / HS	Type HA							
D 12	D 14	D 16	M 8	M 10	6	20	100	5	17	13	20

Specification

Stainless steel AISI 304

RoHS

3

NI

Connecting elements GN 6473.2 fasten side guides or retaining profiles for side guide segments on conveyor sections. This also requires the use of side guide brackets GN 6476, GN 6476.2 or GN 6476.3.

Technical Information

Stainless Steel Characteristics

Page

QVX

see also...

	Page
GN 6471 Side Guides	QVX
GN 6472 Side Guides	QVX
GN 6473.1 Retaining Profiles	QVX
GN 6476 / GN 6476.2 / GN 6476.3 Side Guide Brackets	QVX ff.

How to order (Type S)

1	Type
3	Material

GN 6473.2-S-NI

How to order (Type H / HA / HS)

1	Type
2	d ₁
3	Material

GN 6473.2-HS-D14-NI

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9
3.10

