


elesa
Original design MPG-C / MPG-T



- 1 Type**
- T** Retaining profile trapezoidal
 - R** Retaining profile round

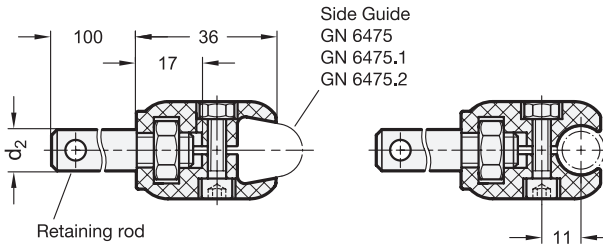

2 d_1 Type R			2 h Type T	3 d_2 Retaining rod			b_0		
B 10	B 12	B 14	17	D 12	D 14	D 16	GN 6475 18 / 21	GN 6475.1 18	GN 6475.2 20

Specification

Clamp

- Plastic, polyamide (PA)
- Operating temperature -30 °C to +100 °C
- Shock resistant
- Black

Retaining rod / Socket cap screws / Nuts

Stainless steel AISI 304

RoHS

Side guide clamps GN 6475.4 attach side guides to conveyor sections. The version with retaining rod additionally requires the use of side guide holders GN 6476, GN 6476.2 or GN 6476.3. The version with an internal thread enables direct mounting, for example on a side wall.

see also...

	Page
GN 6475 Side Guides (Guide Contour Flat)	QVX
GN 6475.1 Side Guides (Guide Contour Rounded)	QVX
GN 6475.2 Side Guides (Guide Contour Flat, Stepped)	QVX
GN 6476 Side Guide Brackets (Rigid, with Contact Edge)	QVX
GN 6476.2 Side Guide Brackets (Swiveling, with Contact Edge)	QVX
GN 6476.3 Side Guide Brackets (Swiveling)	QVX
GN 990 Construction Tubes	QVX

Technical Information

Plastic Characteristics	QVX
Stainless Steel Characteristics	QVX

How to order (Without retaining rod)

1 2	1 Type
GN 6475.4-T-17	2 h (d ₁)

How to order (With retaining rod)

1 2 3	1 Type
GN 6475.4-R-B10-D16	2 d ₁ (h)
	3 d ₂