


**Application example**

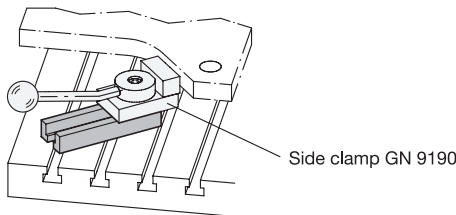

1 <b>b<sub>1</sub></b>	2 <b>l<sub>1</sub></b>	3 <b>d</b>	<b>b<sub>2</sub></b>	<b>b<sub>3</sub></b>	<b>h<sub>1</sub></b>	<b>h<sub>2</sub></b>	<b>l<sub>2</sub></b>	<b>l<sub>3</sub></b>	For side clamp slot width a		
									GN 9190	GN 9190.1	GN 9190.2
30	100	M 8	15	9	15	6,5	63	20	10	10	10
40	120	M 12	20	13	20	7,5	72	25	12	14	14
60	140	M 16	26	17	30	13	80	30	-	18	18

**Specification**

- Steel
  - Tempered
  - Blackened
- RoHS

**Information**

Slotted support blocks GN 9190.3 are provided as accessory for side clamps GN 9190 / GN 9190.1 / GN 9190.2.

They can also be used to fasten side clamps across the T-slot in any position.

see also...

- Side Clamps GN 9190 (with Eccentric Cam Lever) → Page QVX
- Side Clamps GN 9190.1 (with Clamping Thread) → Page QVX
- Side Clamps GN 9190.2 (with Support) → Page QVX

**How to order**

**GN 9190.3-30-100-M8**

1	b <sub>1</sub>
2	l <sub>1</sub>
3	d

