



Type A

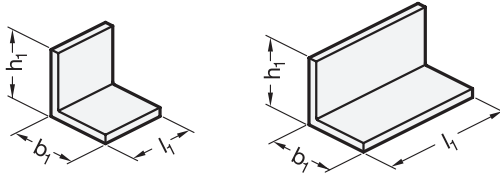

Type B

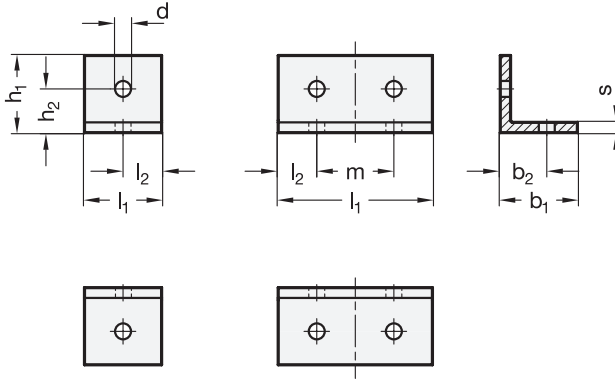

5 Type

- A Without bores
- B With bores

2

3

4

h ₁		b ₁	l ₁	b ₂	d	h ₂	l ₂	m	s
ALM	STB								
30	30	30	30	18	6,2	18	15	-	4
30	30	30	60	18	6,2	18	15	30	4
40	40	40	40	24	8,2	24	20	-	5
40	40	40	80	24	8,2	24	20	40	5
50	-	50	50	30	10,2	30	25	-	6
50	-	50	100	30	10,2	30	25	50	6

Specification

- Structural steel
Drawn, with sharp edges
Blackened
- Aluminum
Pressed
Matte finish, tumbled
- RoHS

1

Information

STB

Installation brackets GN 970 are used universally for right-angle connecting and fastening of, e.g. base plates or covers.

ALM

Type A allows for the use of drilling templates specific to the application as well as fastening by welding.

Type B installation brackets have 2 or 4 holes depending on the length l₁.

see also...

- Angle Pieces, Shackles GN 967 → Page 1827

How to order

1	Material
2	h ₁
3	b ₁
4	l ₁
5	Type

GN970-STB-40-40-80-A